


Soft Down Stays - Selection Help

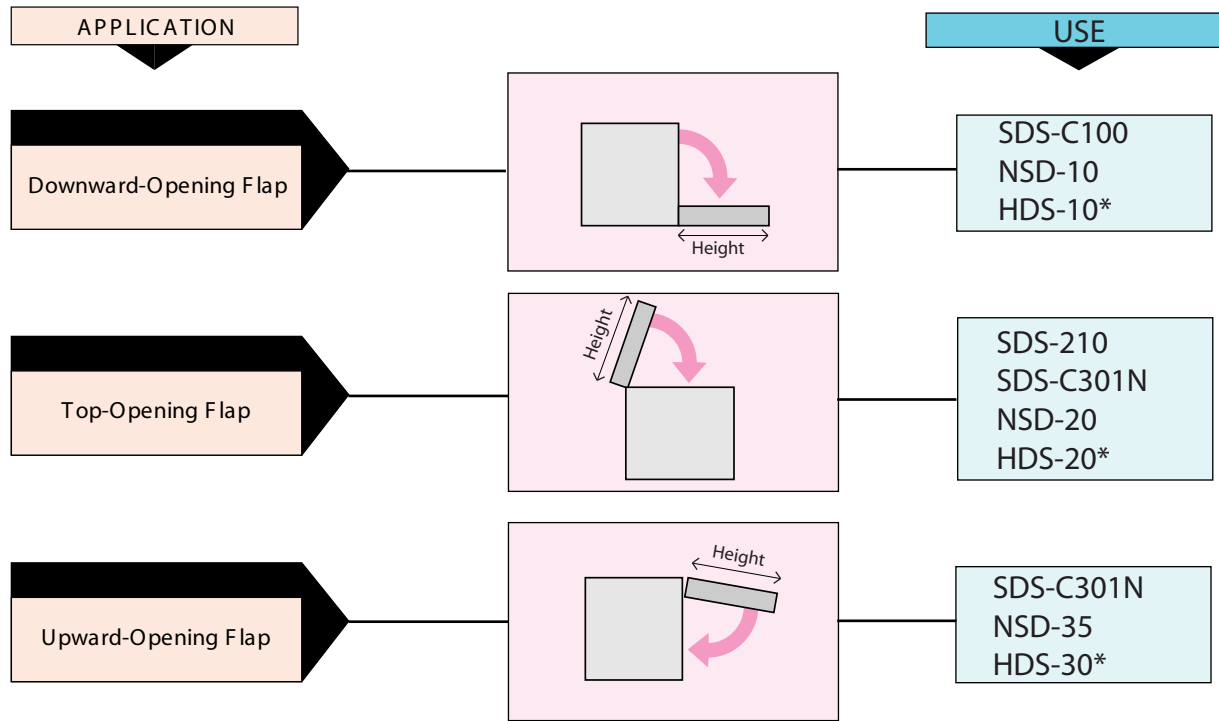

* Note - The HDS comes in 3 versions
Light Duty (K), Medium Duty (M), Heavy Duty (H)

Weight Range in Lbs per Pair

Height (Inches)	SDS		SDS-C301N		NSD		HDS-K		HDS-M		HDS-H	
	Min	Max	Min	Max	Min	Max	Min	Max	Min	Max	Min	Max
8	15.00	21.50	17.50	30.00	9.50	30.00	30.25	43.25	43.25	54.00	54.00	65.00
9	13.33	19.11	15.56	26.67	8.44	26.67	26.89	38.44	38.44	48.00	48.00	57.78
10	12.00	17.20	14.00	24.00	7.60	24.00	24.20	34.60	34.60	43.20	43.20	52.00
11	10.91	15.64	12.73	21.82	6.91	21.82	22.00	31.45	31.45	39.27	39.27	47.27
12	10.00	14.33	11.67	20.00	6.33	20.00	20.17	28.83	28.83	36.00	36.00	43.33
13	9.23	13.23	10.77	18.46	5.85	18.46	18.62	26.62	26.62	33.23	33.23	40.00
14	8.57	12.29	10.00	17.14	5.43	17.14	17.29	24.71	24.71	30.86	30.86	37.14
15	8.00	11.47	9.33	16.00	5.07	16.00	16.13	23.07	23.07	28.80	28.80	34.67
16	7.50	10.75	8.75	15.00	4.75	15.00	15.13	21.63	21.63	27.00	27.00	32.50
17	7.06	10.12	8.24	14.12	4.47	14.12	14.24	20.35	20.35	25.41	25.41	30.59
18	6.67	9.56	7.78	13.33	4.22	13.33	13.44	19.22	19.22	24.00	24.00	28.89
19	6.32	9.05	7.37	12.63	4.00	12.63	12.74	18.21	18.21	22.74	22.74	27.37
20	6.00	8.60	7.00	12.00	3.80	12.00	12.10	17.30	17.30	21.60	21.60	26.00
21	5.71	8.19	6.67	11.43	3.62	11.43	11.52	16.48	16.48	20.57	20.57	24.76
22	5.45	7.82	6.36	10.91	3.45	10.91	11.00	15.73	15.73	19.64	19.64	23.64
23	5.22	7.48	6.09	10.43	3.30	10.43	10.52	15.04	15.04	18.78	18.78	22.61
24	5.00	7.17	5.83	10.00	3.17	10.00	10.08	14.42	14.42	18.00	18.00	21.67
25	4.80	6.88	5.60	9.60	3.04	9.60	9.68	13.84	13.84	17.28	17.28	20.80
26	4.62	6.62	5.38	9.23	2.92	9.23	9.31	13.31	13.31	16.62	16.62	20.00