


SLIDING DOOR HANDLE

DSI-3020

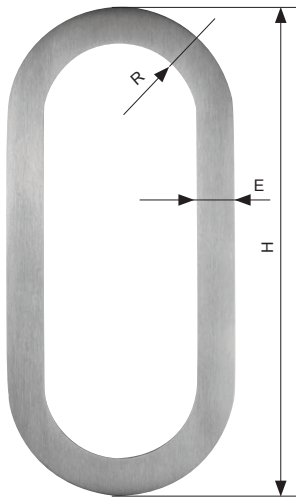


- Surface-mount handle.
- Sold as a set. Each set includes 2 metal handles.

| Item No. | H | E | R | Thickness (mm) | Material | | Box (sets) | Carton (sets) |
|--------------|-------------------|----|----|----------------|---------------------|---------------------|------------|---------------|
| | | | | | 304 Stainless Steel | Finish | | |
| DSI-3020-85 | 85 (3-3/8") | 8 | 12 | 6 (1/4") | 70 | 304 Stainless Steel | 1 | 10 |
| DSI-3020-150 | 150 (5-7/8") | 12 | 23 | | 125 | | | |
| DSI-3020-300 | 300 (11-13/16") | 16 | 24 | | 250 | | | |

SLIDING DOOR HANDLE

DSI-4020

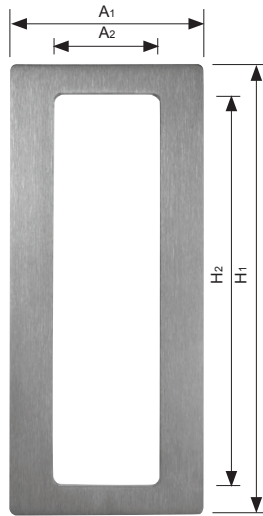


- Surface-mount handle.
- Sold as a set. Each set includes 2 metal handles.

| Item No. | H ₁ | H ₂ | A ₁ | A ₂ | Thickness (mm) | Material | | Box (sets) | Carton (sets) |
|--------------|-------------------|----------------|----------------|----------------|----------------|---------------------|---------------------|------------|---------------|
| | | | | | | 304 Stainless Steel | Finish | | |
| DSI-4020-85 | 85 (3-3/8") | 65 (2-9/16") | 50 (2") | 20 (13/16") | 6 (1/4") | 135 | 304 Stainless Steel | 1 | 10 |
| DSI-4020-150 | 150 (5-7/8") | 130 (5-1/8") | 65 (2-9/16") | 35 (1-3/8") | | 240 | | | |
| DSI-4020-300 | 300 (11-13/16") | 280 (11") | 80 (3-3/16") | 50 (2") | | 480 | | | |

SLIDING DOOR HANDLE

DSI-4040

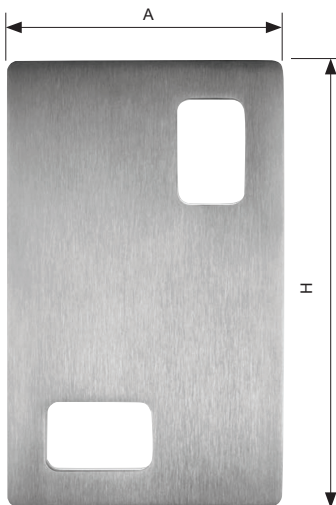

- Surface-mount handle.
- Sold as a set. Each set includes 2 metal handles.

| Item No. | H | A | Thickness (mm) | Material | | Box (sets) | Carton (sets) |
|--------------|-------------------|-----------------|----------------|---------------------|---------------------|------------|---------------|
| | | | | 304 Stainless Steel | Finish | | |
| DSI-4040-85 | 85 (3-3/8") | 50 (2") | 6 (1/4") | 70 | 304 Stainless Steel | 1 | 10 |
| DSI-4040-150 | 150 (5-7/8") | 92 (3-5/8") | | 125 | | | |
| DSI-4040-300 | 300 (11-13/16") | 185 (7-5/16") | | 250 | | | |