


### HANDLE (1/2" BAR PULL)



### 16 SERIES

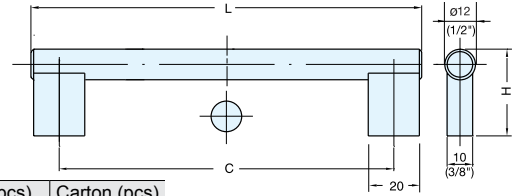


Item No.	L	C	H	Weight (g)	Box (pcs)	Carton (pcs)
1646	118	96 ( 3-25/32" )	34 (1-11/32")	62	25	250
1647	150	128 ( 5-1/32" )		70		
1648	182	160 ( 6-5/16" )		85		
1650	214	192 ( 7-9/16" )		94		
1651	314	292 ( 11-7/16" )		121		
1652	342	320 ( 12-9/16" )		128		
1653	364	342 ( 13-7/16" )		134		
1654	414	392 ( 15-7/16" )		148		
1655	514	492 ( 19-3/8" )		175		
1656	614	592 ( 23-5/16" )		202		

Material	Finish
304 Stainless Steel	Satin

### HANDLE (11/16" BAR PULL)



### 27 SERIES

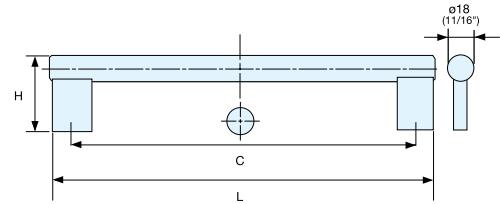



Item No.	L	C	H	Weight (g)	Box (pcs)	Carton (pcs)
27096	128	96 ( 3-25/32" )	44 (1-47/64")	140	15	150
27128	160	128 ( 5-1/32" )		152		
27160	192	160 ( 6-5/16" )		170		
27192	224	192 ( 7-9/16" )		183		
27292	324	292 ( 11-7/16" )		225		
27320	352	320 ( 12-9/16" )		237		
27342	374	342 ( 13-15/32" )		245		
27392	424	392 ( 15-7/16" )		267		
27492	524	492 ( 19-3/8" )		309		
27592	624	592 ( 23-5/16" )		351		

Material	Finish
304 Stainless Steel	Satin

### HANDLE (MITERED CORNER)



### DIH

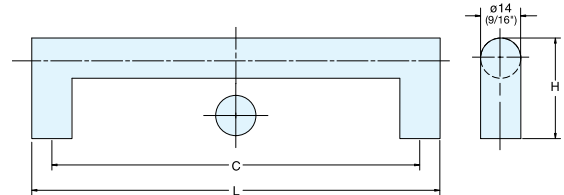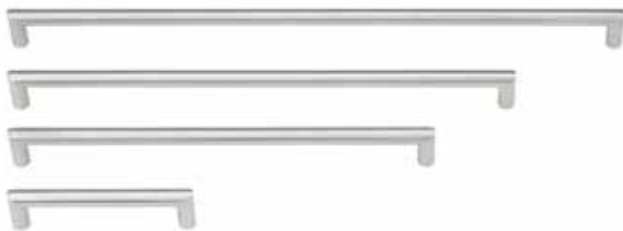

Item No.	L	C	H	Weight (g)	Box (pcs)	Carton (pcs)
DIH-096	110	96 ( 3-25/32" )	35 (1-3/8")	57	25	250
DIH-128	142	128 ( 5-1/32" )		66		
DIH-192	206	192 ( 7-9/16" )		83		
DIH-342	356	342 ( 13-15/32" )		123		
DIH-492	506	492 ( 19-3/8" )		163		
DIH-592	606	592 ( 23-5/16" )		189		

Material	Finish
304 Stainless Steel	Satin