


# CONCEALED HINGE (INSET)



# 230-26/0T, C26/0T

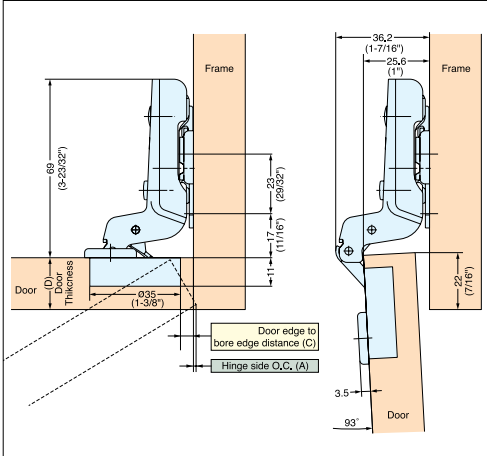


■ Hinge side opening clearance chart

Door thickness (D)	Door edge to bore edge distance (C)		
	3	4	5
15	0.0	0.0	0.0
16	0.1	0.1	0.1
17	0.1	0.1	0.1
18	0.3	0.3	0.2
19	0.4	0.4	0.4
20	0.6	0.6	0.6
21	0.9	0.8	0.8
22	1.2	1.2	1.1

Hinge side O.C. (A)

\*Mounting Plate sold separately. See P.299

\*Mounting Screw sold separately. See TAP3515NI on P.299

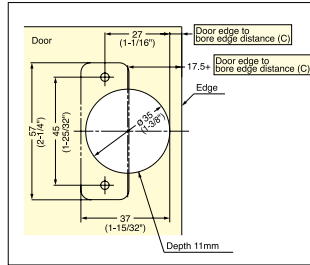


Bore Dimensions

Item No.	Type	Weight (g)	Carton (pcs)	Material	Finish
230-26/0T	Free Swinging	60	200	Steel	Nickel
230-C26/0T	Self-Closing				


# MOUNTING PLATE FOR 230 SERIES HINGES




230-P4W-32T

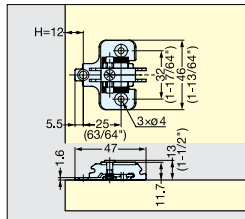


230-P4W-32T + 2

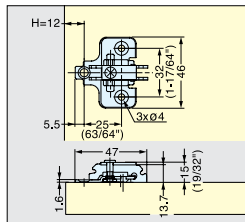

230-P4W-32T + 5

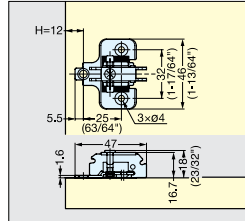

Installation

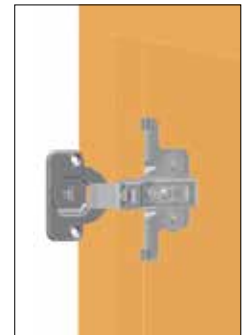

Face Frame Bracket for 230 Mounting Plate. See P.344 (Sold separately)



TAP3515 NI (Sold separately)

Item No.	Weight (g)	Carton (pcs)	Material	Finish
230-P4W-32T	40	400	Steel	Nickel
230-P4W-32T + 2		400		
230-P4W-32T + 5		400		