

## THICK DOOR CONCEALED HINGE (26mm OVERLAY)



## H230-26/26T, C26/26T



■ Door edge to bore edge distance (C) and Overlay distance (B) Table 1.



Door edge to bore edge distance (C)	3	4	5	6	7
Overlay distance (B)	22	23	24	25	26

■ Hinge side opening clearance chart Table 2.

Door thickness (D)	Door edge to bore edge distance (C)				
	3	4	5	6	7
18	0.2	0.2	0.2	0.2	0.2
20	0.4	0.4	0.4	0.4	0.4
22	0.7	0.7	0.6	0.6	0.6
24	1.0	1.0	1.0	1.0	0.9
26	1.4	1.4	1.3	1.3	1.3
28	2.7	1.9	1.8	1.8	1.8
30	5.1	4.1	3.1	2.4	2.3
32	7.5	6.5	5.5	4.5	3.5
34	9.9	8.9	7.9	6.9	5.9

Hinge side O.C. (A)

\*Mounting Plate sold separately. See P.303  
 \*Mounting Screw sold separately. See TAP3515NI on P.303

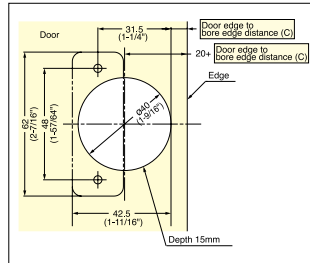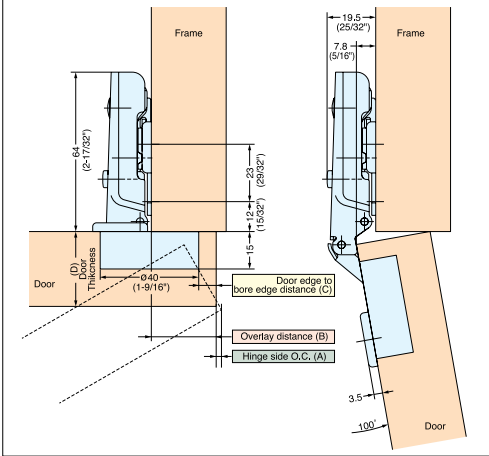

Bore Dimensions

Item No.	Type	Weight (g)	Carton (pcs)	Material	Finish
H230-26/26T	Free Swinging	60	200	Steel	Nickel
H230-C26/26T	Self-Closing				

## THICK DOOR CONCEALED HINGE (16mm OVERLAY)



## H230-26/16T, C26/16T



■ Door edge to bore edge distance (C) and Overlay distance (B) Table 1.



Door edge to bore edge distance (C)	3	4	5	6	7
Overlay distance (B)	12	13	14	15	16

■ Hinge side opening clearance chart Table 2.

Door thickness (D)	Door edge to bore edge distance (C)				
	3	4	5	6	7
18	0.2	0.2	0.2	0.2	0.2
20	0.4	0.4	0.4	0.4	0.4
22	0.7	0.7	0.6	0.6	0.6
24	1.0	1.0	1.0	1.0	0.9
26	1.4	1.4	1.3	1.3	1.3
28	2.7	1.9	1.8	1.8	1.8
30	5.1	4.1	3.1	2.4	2.3
32	7.5	6.5	5.5	4.5	3.5
34	9.9	8.9	7.9	6.9	5.9

Hinge side O.C. (A)

\*Mounting Plate sold separately. See P.303  
 \*Mounting Screw sold separately. See TAP3515NI on P.303

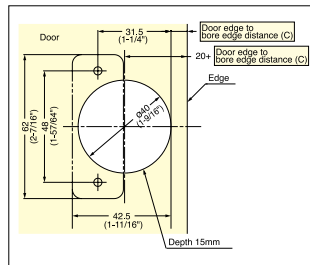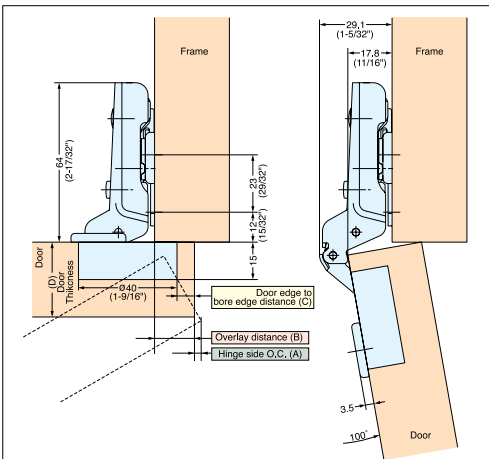

Bore Dimensions

Item No.	Type	Weight (g)	Carton (pcs)	Material	Finish
H230-26/16T	Free Swinging	60	200	Steel	Nickel
H230-C26/16T	Self-Closing				