

POCKET DOOR SYSTEM (OVERLAY)

ALT-ST20-D10


LATERAL OPEN
CABINET HARDWARE

POCKET DOOR SYSTEM




- Overlay Pocket Door System with door alignment adjustability.
- Overlay amount is up to 3/8" (10 mm).
- Overlay damper unit with adjustment screw included with package.
- The damper hinges can be replaced with hinges with catch function.
- The hanging angle of the door can be easily adjusted to counteract and prevent door sag. When installing, the door can be lifted upward into 5 positions.
- The sliding system allows doors to recede inside cabinets. Doors will occupy minimal amount of space, providing full access to cabinet interior.
- Available slide lengths: 16", 19", 22", 24" and 28".
- Durability: successfully passed 40,000 open/close private cycles.

Installation Example

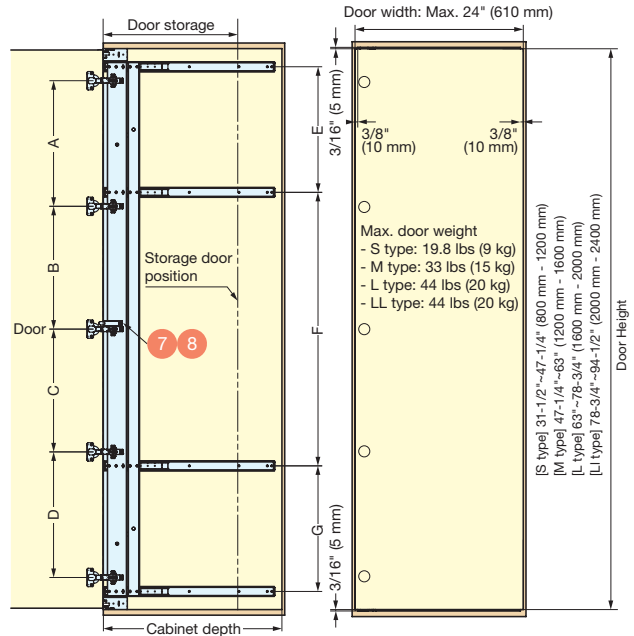


Easy Door Alignment Adjustment

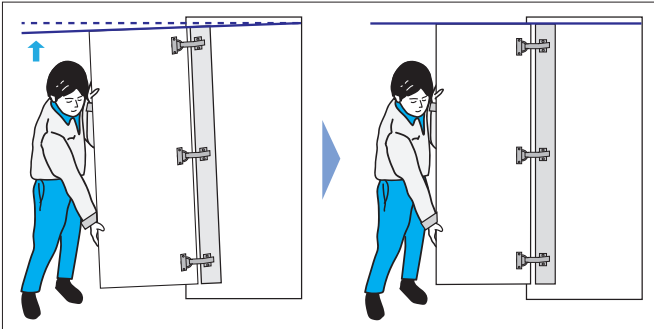


When installing, you can adjust the hanging angle just by lifting up the door.


Installation Example

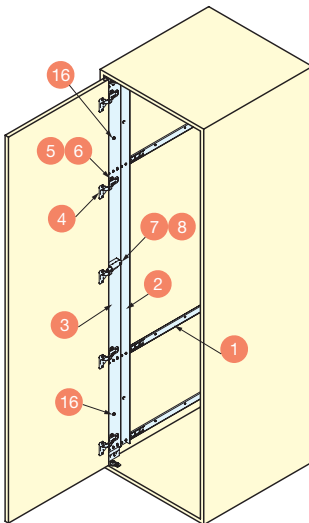

Cut Out Dimensions

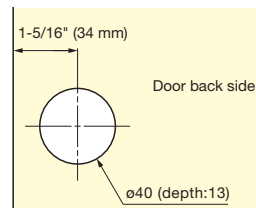

- Number of slides
- S type : 2 pcs
- M type : 2 pcs
- L type : 4 pcs
- LL type : 4 pcs

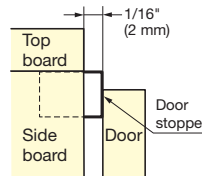

Use on Double Doors

Set a door bumper or stopper on the leading edge side to prevent contact between door and side board.

Last Digits of Item Name (Parts Set)	Door Storage Amount	Min. Cabinet Depth
16	10-9/16" (268 mm)	16-9/16" (420 mm)
19	13-9/16" (344 mm)	19-1/2" (496 mm)
22	16-9/16" (420 mm)	22-1/2" (572 mm)
24	18-9/16" (471 mm)	24-1/2" (623 mm)
28	22-9/16" (573 mm)	28-9/16" (725 mm)

Type	Hinge Pitch				Slide Pitch		
	A	B	C	D	E	F	G
S Type	22-13/16" (580 mm)	-	-	-	26-3/4" (680 mm)	-	-
M Type	19-5/16" (490 mm)	19-5/16" (490 mm)	-	-	23-1/4" (590 mm)	19-5/16" (490 mm)	-
L Type	19-11/16" (500 mm)	14-15/16" (380 mm)	19-11/16" (500 mm)	-	19-11/16" (500 mm)	18-7/8" (480 mm)	19-11/16" (500 mm)
LL Type	17-3/4" (450 mm)	17-5/16" (440 mm)	17-5/16" (440 mm)	17-3/4" (450 mm)	17-3/4" (450 mm)	38-9/16" (980 mm)	17-3/4" (450 mm)

	ALT-ST20-D10S (2 slides)	ALT-ST20-D10M (3 slides)	ALT-ST20-D10L (4 slides)	ALT-ST20-D10LL (4 slides)
Door Width	Max. 24" (610 mm)			
Door Height	31-1/2"~47-1/4" (800 - 1200 mm)	47-1/4"~63" (1200 - 1600 mm)	63"~78-3/4" (1600 - 2000 mm)	78-3/4"~94-1/2" (2000 - 2400 mm)
Door Thickness	11/16"~13/16" (18 - 20 mm)			
Door Weight	Max. 19.8 lbs (9 kg)	Max. 33 lbs (15 kg)	Max. 44 lbs (20 kg)	

How to Order ALT-ST20-D10

Parts set Not optional. Each set includes required parts.

Type	Door Spec (Thickness: 11/16" ~ 1-3/16" (18-30 mm))	C Door Storage	D Min. Cabinet Depth	Item Name
S		10-9/16" (268 mm)	16-9/16" (420 mm)	ALT-ST20-D10S-16
		13-9/16" (344 mm)	19-1/2" (496 mm)	ALT-ST20-D10S-19
		16-9/16" (420 mm)	22-1/2" (572 mm)	ALT-ST20-D10S-22
		18-9/16" (471 mm)	24-1/2" (623 mm)	ALT-ST20-D10S-24
		22-9/16" (573 mm)	28-9/16" (725 mm)	ALT-ST20-D10S-28
W= Max. 24" (610 mm) Weight= Max. 19.8 lbs (9 kg) H= 31-1/2"~47-1/4" (800-1200 mm)				
M		10-9/16" (268 mm)	16-9/16" (420 mm)	ALT-ST20-D10M-16
		13-9/16" (344 mm)	19-1/2" (496 mm)	ALT-ST20-D10M-19
		16-9/16" (420 mm)	22-1/2" (572 mm)	ALT-ST20-D10M-22
		18-9/16" (471 mm)	24-1/2" (623 mm)	ALT-ST20-D10M-24
		22-9/16" (573 mm)	28-9/16" (725 mm)	ALT-ST20-D10M-28
W= Max. 24" (610 mm) Weight= Max. 33 lbs (15 kg) H= 47-1/4"~63" (1200-1600 mm)				
L		10-9/16" (268 mm)	16-9/16" (420 mm)	ALT-ST20-D10L-16
		13-9/16" (344 mm)	19-1/2" (496 mm)	ALT-ST20-D10L-19
		16-9/16" (420 mm)	22-1/2" (572 mm)	ALT-ST20-D10L-22
		18-9/16" (471 mm)	24-1/2" (623 mm)	ALT-ST20-D10L-24
		22-9/16" (573 mm)	28-9/16" (725 mm)	ALT-ST20-D10L-28
W= Max. 24" (610 mm) Weight= Max. 44 lbs (20 kg) H= 63"~78-3/4" (1600-2000 mm)				
LL		10-9/16" (268 mm)	16-9/16" (420 mm)	ALT-ST20-D10LL-16
		13-9/16" (344 mm)	19-1/2" (496 mm)	ALT-ST20-D10LL-19
		16-9/16" (420 mm)	22-1/2" (572 mm)	ALT-ST20-D10LL-22
		18-9/16" (471 mm)	24-1/2" (623 mm)	ALT-ST20-D10LL-24
		22-9/16" (573 mm)	28-9/16" (725 mm)	ALT-ST20-D10LL-28
W= Max. 24" (610 mm) Weight= Max. 44 lbs (20 kg) H= 78-3/4"~94-1/2" (2000-2400 mm)				


Item Name of Parts Set

ALT-ST15-D10 S - 16

Type Name _____
Slide Length _____


Installation of Slide

Cross section a: Slide/hinge mounting

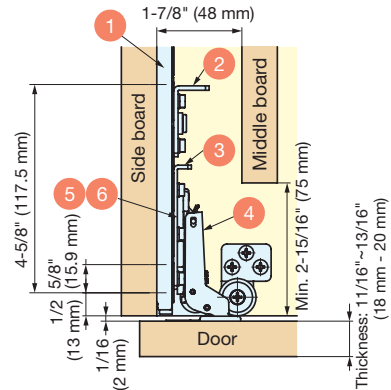


To hide the metal fittings, install a middle board (not included).
(An attachable/detachable middle board is recommended for easier maintenance.)

Cross section b: For roller bracket mounting

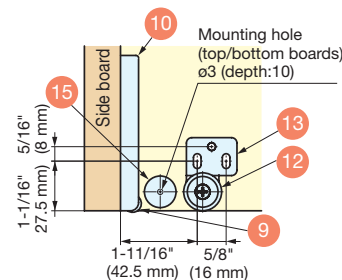

Cross section b: For mounting with female screw

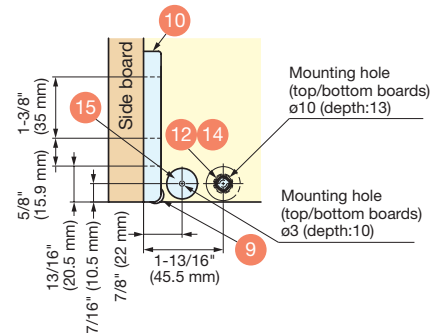

ALT-ST20-D10 Parts Set Details

The following 1 - 15 show detailed information on the set codes included on the previous page.

No.	Qty				Parts	Dimensions	Item Name																																													
	S	M	L	LL																																																
1						AL127C-16																																														
						AL127C-19																																														
						AL127C-22																																														
						AL127C-24																																														
						AL127C-28																																														
						<table border="1"> <thead> <tr> <th>Item Name</th> <th>Slide Length</th> <th>Travel Length</th> <th>Door Storage</th> <th>A</th> <th>B</th> <th>C</th> <th>D</th> </tr> </thead> <tbody> <tr> <td>AL127C-16</td> <td>16-3/16" (411.4 mm)</td> <td>11-11/16" (296.4 mm)</td> <td>10-9/16" (268 mm)</td> <td>15-1/4" (387.4 mm)</td> <td>14-5/8" (371.5 mm)</td> <td>10-5/8" (269.9 mm)</td> <td>-</td> </tr> <tr> <td>AL127C-19</td> <td>19-3/16" (487.6 mm)</td> <td>13-5/8" (345.6 mm)</td> <td>13-9/16" (344 mm)</td> <td>17-3/16" (436.6 mm)</td> <td>17-3/16" (447.7 mm)</td> <td>13-5/8" (346.1 mm)</td> <td>9-1/8" (231.8 mm)</td> </tr> <tr> <td>AL127C-22</td> <td>22-3/16" (563.8 mm)</td> <td>16-5/8" (421.8 mm)</td> <td>16-9/16" (420 mm)</td> <td>21-1/4" (539.8 mm)</td> <td>20-5/8" (523.9 mm)</td> <td>16-5/8" (422.3 mm)</td> <td>10-5/8" (269.9 mm)</td> </tr> <tr> <td>AL127C-24</td> <td>24-3/16" (614.6 mm)</td> <td>18-5/8" (472.6 mm)</td> <td>18-9/16" (471 mm)</td> <td>23-1/4" (590.6 mm)</td> <td>22-5/8" (574.7 mm)</td> <td>18-5/8" (473.1 mm)</td> <td>11-5/8" (295.3 mm)</td> </tr> <tr> <td>AL127C-28</td> <td>28-3/16" (716.2 mm)</td> <td>22-5/8" (574.2 mm)</td> <td>22-9/16" (573 mm)</td> <td>27-1/4" (692.2 mm)</td> <td>26-5/8" (676.3 mm)</td> <td>22-5/8" (574.7 mm)</td> <td>13-5/8" (346.1 mm)</td> </tr> </tbody> </table>	Item Name	Slide Length	Travel Length	Door Storage	A	B	C	D	AL127C-16	16-3/16" (411.4 mm)	11-11/16" (296.4 mm)	10-9/16" (268 mm)	15-1/4" (387.4 mm)	14-5/8" (371.5 mm)	10-5/8" (269.9 mm)	-	AL127C-19	19-3/16" (487.6 mm)	13-5/8" (345.6 mm)	13-9/16" (344 mm)	17-3/16" (436.6 mm)	17-3/16" (447.7 mm)	13-5/8" (346.1 mm)	9-1/8" (231.8 mm)	AL127C-22	22-3/16" (563.8 mm)	16-5/8" (421.8 mm)	16-9/16" (420 mm)	21-1/4" (539.8 mm)	20-5/8" (523.9 mm)	16-5/8" (422.3 mm)	10-5/8" (269.9 mm)	AL127C-24	24-3/16" (614.6 mm)	18-5/8" (472.6 mm)	18-9/16" (471 mm)	23-1/4" (590.6 mm)	22-5/8" (574.7 mm)	18-5/8" (473.1 mm)	11-5/8" (295.3 mm)	AL127C-28	28-3/16" (716.2 mm)	22-5/8" (574.2 mm)	22-9/16" (573 mm)	27-1/4" (692.2 mm)	26-5/8" (676.3 mm)
Item Name	Slide Length	Travel Length	Door Storage	A	B	C	D																																													
AL127C-16	16-3/16" (411.4 mm)	11-11/16" (296.4 mm)	10-9/16" (268 mm)	15-1/4" (387.4 mm)	14-5/8" (371.5 mm)	10-5/8" (269.9 mm)	-																																													
AL127C-19	19-3/16" (487.6 mm)	13-5/8" (345.6 mm)	13-9/16" (344 mm)	17-3/16" (436.6 mm)	17-3/16" (447.7 mm)	13-5/8" (346.1 mm)	9-1/8" (231.8 mm)																																													
AL127C-22	22-3/16" (563.8 mm)	16-5/8" (421.8 mm)	16-9/16" (420 mm)	21-1/4" (539.8 mm)	20-5/8" (523.9 mm)	16-5/8" (422.3 mm)	10-5/8" (269.9 mm)																																													
AL127C-24	24-3/16" (614.6 mm)	18-5/8" (472.6 mm)	18-9/16" (471 mm)	23-1/4" (590.6 mm)	22-5/8" (574.7 mm)	18-5/8" (473.1 mm)	11-5/8" (295.3 mm)																																													
AL127C-28	28-3/16" (716.2 mm)	22-5/8" (574.2 mm)	22-9/16" (573 mm)	27-1/4" (692.2 mm)	26-5/8" (676.3 mm)	22-5/8" (574.7 mm)	13-5/8" (346.1 mm)																																													
<p>The item number with the same last digits as those of the set item number is included in each set.</p>																																																				
<p>Material: Steel Finish: Chromate</p>																																																				
2		1			ALT-ST20-S																																															
					ALT-ST20-M																																															
					ALT-ST20-L																																															
					ALT-ST20-LL																																															
					<table border="1"> <thead> <tr> <th>Item Name</th> <th>A</th> <th>B</th> <th>C</th> <th>Full Length L</th> </tr> </thead> <tbody> <tr> <td>ALT-ST20-S</td> <td>26-3/4" (680 mm)</td> <td>-</td> <td>-</td> <td>27-15/16" (710 mm)</td> </tr> <tr> <td>ALT-ST20-M</td> <td>19-5/16" (490 mm)</td> <td>3-15/16" (100 mm)</td> <td>19-5/16" (490 mm)</td> <td>43-11/16" (1110 mm)</td> </tr> <tr> <td>ALT-ST20-L</td> <td>19-11/16" (500 mm)</td> <td>18-7/8" (480 mm)</td> <td>19-11/16" (500 mm)</td> <td>59-7/16" (1510 mm)</td> </tr> <tr> <td>ALT-ST20-LL</td> <td>17-3/4" (450 mm)</td> <td>38-9/16" (980 mm)</td> <td>17-3/4" (450 mm)</td> <td>75-3/16" (1910 mm)</td> </tr> </tbody> </table>	Item Name	A	B	C	Full Length L	ALT-ST20-S	26-3/4" (680 mm)	-	-	27-15/16" (710 mm)	ALT-ST20-M	19-5/16" (490 mm)	3-15/16" (100 mm)	19-5/16" (490 mm)	43-11/16" (1110 mm)	ALT-ST20-L	19-11/16" (500 mm)	18-7/8" (480 mm)	19-11/16" (500 mm)	59-7/16" (1510 mm)	ALT-ST20-LL	17-3/4" (450 mm)	38-9/16" (980 mm)	17-3/4" (450 mm)	75-3/16" (1910 mm)																						
Item Name	A	B	C	Full Length L																																																
ALT-ST20-S	26-3/4" (680 mm)	-	-	27-15/16" (710 mm)																																																
ALT-ST20-M	19-5/16" (490 mm)	3-15/16" (100 mm)	19-5/16" (490 mm)	43-11/16" (1110 mm)																																																
ALT-ST20-L	19-11/16" (500 mm)	18-7/8" (480 mm)	19-11/16" (500 mm)	59-7/16" (1510 mm)																																																
ALT-ST20-LL	17-3/4" (450 mm)	38-9/16" (980 mm)	17-3/4" (450 mm)	75-3/16" (1910 mm)																																																
<p>The end of the item number indicates the corresponding size.</p>																																																				
<p>Material: Aluminum Alloy Finish: Silver Anodized</p>																																																				
3		1		ALT-ST20-LPS																																																
				ALT-ST20-LPM																																																
				ALT-ST20-LPL																																																
				ALT-ST20-LPLL																																																
				<table border="1"> <thead> <tr> <th rowspan="2">Type</th> <th colspan="4">Hinge Pitch</th> <th colspan="3">Slide Pitch</th> <th rowspan="2">Full Length L</th> </tr> <tr> <th>A</th> <th>B</th> <th>C</th> <th>D</th> <th>E</th> <th>F</th> <th>G</th> </tr> </thead> <tbody> <tr> <td>ALT-ST20-LPS</td> <td>22-13/16" (580 mm)</td> <td>-</td> <td>-</td> <td>-</td> <td>26-3/4" (680 mm)</td> <td>-</td> <td>-</td> <td>27-15/16" (710 mm)</td> </tr> <tr> <td>ALT-ST20-LPM</td> <td>19-5/16" (490 mm)</td> <td>19-5/16" (490 mm)</td> <td>-</td> <td>-</td> <td>23-1/4" (590 mm)</td> <td>3-15/16" (100 mm)</td> <td>19-5/16" (490 mm)</td> <td>43-11/16" (1110 mm)</td> </tr> <tr> <td>ALT-ST20-LPL</td> <td>19-11/16" (500 mm)</td> <td>14-15/16" (380 mm)</td> <td>19-11/16" (500 mm)</td> <td>-</td> <td>19-11/16" (500 mm)</td> <td>18-7/8" (480 mm)</td> <td>19-11/16" (500 mm)</td> <td>59-7/16" (1510 mm)</td> </tr> <tr> <td>ALT-ST20-LPLL</td> <td>17-3/4" (450 mm)</td> <td>17-5/16" (440 mm)</td> <td>17-5/16" (440 mm)</td> <td>17-3/4" (450 mm)</td> <td>17-3/4" (450 mm)</td> <td>38-9/16" (980 mm)</td> <td>17-3/4" (450 mm)</td> <td>75-3/16" (1910 mm)</td> </tr> </tbody> </table>	Type	Hinge Pitch				Slide Pitch			Full Length L	A	B	C	D	E	F	G	ALT-ST20-LPS	22-13/16" (580 mm)	-	-	-	26-3/4" (680 mm)	-	-	27-15/16" (710 mm)	ALT-ST20-LPM	19-5/16" (490 mm)	19-5/16" (490 mm)	-	-	23-1/4" (590 mm)	3-15/16" (100 mm)	19-5/16" (490 mm)	43-11/16" (1110 mm)	ALT-ST20-LPL	19-11/16" (500 mm)	14-15/16" (380 mm)	19-11/16" (500 mm)	-	19-11/16" (500 mm)	18-7/8" (480 mm)	19-11/16" (500 mm)	59-7/16" (1510 mm)	ALT-ST20-LPLL	17-3/4" (450 mm)	17-5/16" (440 mm)	17-5/16" (440 mm)	17-3/4" (450 mm)
Type	Hinge Pitch					Slide Pitch			Full Length L																																											
	A	B	C	D	E	F	G																																													
ALT-ST20-LPS	22-13/16" (580 mm)	-	-	-	26-3/4" (680 mm)	-	-	27-15/16" (710 mm)																																												
ALT-ST20-LPM	19-5/16" (490 mm)	19-5/16" (490 mm)	-	-	23-1/4" (590 mm)	3-15/16" (100 mm)	19-5/16" (490 mm)	43-11/16" (1110 mm)																																												
ALT-ST20-LPL	19-11/16" (500 mm)	14-15/16" (380 mm)	19-11/16" (500 mm)	-	19-11/16" (500 mm)	18-7/8" (480 mm)	19-11/16" (500 mm)	59-7/16" (1510 mm)																																												
ALT-ST20-LPLL	17-3/4" (450 mm)	17-5/16" (440 mm)	17-5/16" (440 mm)	17-3/4" (450 mm)	17-3/4" (450 mm)	38-9/16" (980 mm)	17-3/4" (450 mm)	75-3/16" (1910 mm)																																												
<p>Used in combination with the synchronized board. The end of the item number indicates the corresponding size.</p>																																																				
<p>Material: Aluminum Alloy Finish: Silver Anodized</p>																																																				

*For information on how to mount the parts and the quantities of the parts included in each parts set, please see the instructions.

ALT-ST20-D10 Parts Set Details

The following 1-19 show detailed information on the set codes included on the previous page.


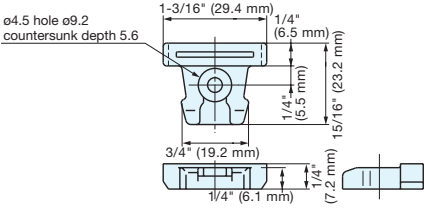

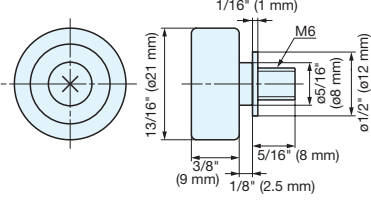

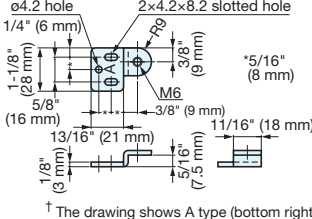

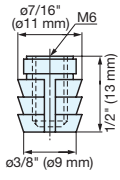

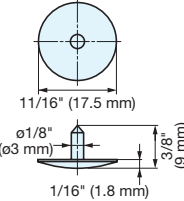
 
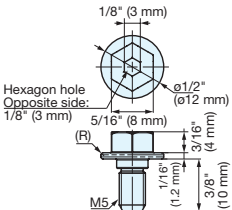

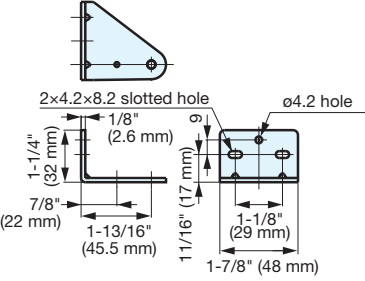
No.	Qty				Parts	Dimensions	Item Name					
	S	M	L	LL								
4	2		3		<p>Hinge body (with catch)</p>	<p>Countersunk hole for 2x nominal 3.5 5/16" (7.5 mm) 11/16" (17.4 mm) 15/16" (23 mm) 1-1/16" (27 mm) 4-9/16" (116.5 mm) 1/2" (13 mm) 2-1/16" (52 mm) 2-5/8" (66 mm) 94°</p>	SCAF-7G99 Material: Zinc Alloy (ZDC) Finish: Nickel					
5	2		3		<p>Hinge mounting plate</p>	<p>Countersunk hole for 2x nominal 3.5 3/4" (19 mm) 1-1/4" (32 mm) 1-7/8" (48 mm) 9/16" (15 mm) 1-1/16" (27.5 mm) 1/2" (12.3 mm) 2-1/2" (64 mm) 1/8" (3.5 mm)</p>	SBAR3R Material: Zinc Alloy (ZDC) Finish: Nickel					
6	2		3		<p>Mounting plate</p>	<p>4xR3 3xM4-6H 1/16" (2 mm) 1/4" (6 mm) 3/4" (19 mm) 5/8" (16 mm) 1-1/8" (29 mm) 1/8" (3.3 mm) Burring</p>	ALT-MP32 Material: Stainless Steel Finish: Barrel Polished					
7			1		<p>Damper unit</p>	<p>Damper adjustment screw 11/16" (17.2 mm) 2-1/2" (64.3 mm) 3-1/4" (83.4 mm) 13/16" (20.7 mm) 1/16" (1.6 mm) Damper colour: Orange</p>	SD0S8SNG Material: Zinc Alloy Finish: Nickel					
8			1		<p>Damper base</p>	<p>11/16" (17.8 mm) 3/4" (18.3 mm) 1/4" (6 mm) 2-9/16" (64.6 mm)</p>	SDARX99 Material: Zinc Alloy Finish: Nickel					
9	2		3		<p>Stopper</p>	<p>1-11/16" (43 mm) 1/4" (6 mm) 7/16" (11.5 mm) 1-9/16" (39.5 mm) 5/16" (7.6 mm) 5/8" (15.9 mm) 2xø6.5 hole 1-3/8" (35.6 mm) 3/8" (9.7 mm) 1" (25 mm)</p>	ALT-ADS Material: Steel/Ethylene Propylene Rubber (EPDM) Finishing/Color: Gloss Chromate/White					
10		2			<p>Protector</p>	<p>1-3/8" (35 mm) 13/16" (20.5 mm) 5/8" (15.9 mm) 1-11/16" (43 mm) 3/8" (10 mm) R4.5 3-3/8" (86 mm)</p>	ALT-ADP Material: Polyacetal (POM) Color: Grey Helps prevent door damage.					
11-16		1			<p>Parts set</p> <div style="display: flex; justify-content: space-around;"> <div style="text-align: center;"> <p>11 Catch</p> </div> <div style="text-align: center;"> <p>12 Roller</p> </div> <div style="text-align: center;"> <p>13 Roller bracket</p> </div> </div> <div style="display: flex; justify-content: space-around; margin-top: 10px;"> <div style="text-align: center;"> <p>14 Insert female screw</p> </div> <div style="text-align: center;"> <p>15 G-type sliding tack</p> </div> <div style="text-align: center;"> <p>16 Adjustment bolt</p> </div> </div>	<table border="1" style="width: 100%; border-collapse: collapse;"> <tr> <td style="padding: 2px;">S type</td> <td rowspan="2" style="padding: 2px;">ALT-ST15-D10-MP</td> </tr> <tr> <td style="padding: 2px;">M type</td> </tr> <tr> <td style="padding: 2px;">L type</td> <td rowspan="2" style="padding: 2px;">ALT-ST15-D10-LLP</td> </tr> <tr> <td style="padding: 2px;">LL type</td> </tr> </table> <p>Necessary types and numbers of screws and hexagon wrenches are included.</p>	S type	ALT-ST15-D10-MP	M type	L type	ALT-ST15-D10-LLP	LL type
S type	ALT-ST15-D10-MP											
M type												
L type	ALT-ST15-D10-LLP											
LL type												

ALT-ST15, ALT-ST20 Parts Set Details

Detailed information on the parts sets used for ALT-ST15 and ALT-ST20

LATERAL OPEN
CABINET HARDWARE

POCKET DOOR SYSTEM

Qty		Parts	Dimensions	Item Name				
S type	M type				L type	LL type		
2		3	  <p> Catch ø4.5 hole ø9.2 countersunk depth 5.6 1-3/16" (29.4 mm) 1/4" (6.5 mm) 1/4" (6.5 mm) 15/16" (23.2 mm) 3/4" (19.2 mm) 1/4" (6.1 mm) 1/4" (7.2 mm) </p>	AL127-CH Material: Polyurethane (PUR) Color: Black				
2			  <p> Roller 1/16" (1 mm) M6 13/16" (ø21 mm) 5/16" (8 mm) 3/8" (9 mm) 1/8" (2.5 mm) 5/16" (ø8 mm) ø1/2" (ø12 mm) </p>	DU19-B4SBR Material: Ethylene Propylene Rubber (EPDM)/Steel Finishing/Color: Gloss Chromate/White				
Left/Right 1 each			  <p> Roller bracket* ø4.2 hole 1/4" (6 mm) 2x4.2x8.2 slotted hole 1-1/8" (28 mm) 5/8" (16 mm) 3/8" (9 mm) 13/16" (21 mm) 1/8" (3 mm) 5/16" (8 mm) 11/16" (18 mm) 5/16" (7.5 mm) M6 † The drawing shows A type (bottom right/upper left) </p>	ALT-2V-AB † Type A (bottom right/ upper left) ALT-2V-BB † Type B (upper right/bottom left) Material: Steel Finish: Colored Chromate				
2			  <p> Insert female screw* ø7/16" (ø11 mm) M6 1/2" (13 mm) 3/8" (ø9 mm) </p>	SC-107-13 Material: Polyamide (PA) Color: White				
2			  <p> G-type sliding tack 11/16" (17.5 mm) ø1/8" (ø3 mm) 3/8" (9 mm) 1/16" (1.8 mm) </p>	G-175 Material: Polyethylene (PE) Color: Natural				
1		2	  <p> Adjustment bolt 1/8" (3 mm) Hexagon hole Opposite side: 1/8" (3 mm) 5/16" (8 mm) 1/16" (1.2 mm) 1/16" (4 mm) 3/8" (10 mm) M5 </p>	ALT-AB M5 Material: Steel (SWCH) Finishing/Color: Colored Chromate (Trivalent)/White Dedicated bolt for hanging adjustment				
1			  <p> Anti-vibration bracket To keep distance between door and floor surface (e.g., laundry room). 2x4.2x8.2 slotted hole ø4.2 hole 1-1/4" (32 mm) 7/8" (22 mm) 1-13/16" (45.5 mm) 1/8" (2.6 mm) 1/16" (17 mm) 1-7/8" (48 mm) 1-1/8" (29 mm) </p>	<table border="1"> <tr> <td>bottom-right/ top-left</td> <td>ALT-2V5BR1</td> </tr> <tr> <td>top-right/ bottom-left</td> <td>ALT-2V5BR2</td> </tr> </table> Material: Steel Finish: Colored Chromate (trivalent)	bottom-right/ top-left	ALT-2V5BR1	top-right/ bottom-left	ALT-2V5BR2
bottom-right/ top-left	ALT-2V5BR1							
top-right/ bottom-left	ALT-2V5BR2							

*Use either roller bracket or insert female screw, depending on the mounting method.